


Patch Cables INDUSTRIAL ETHERNET extraflex

RJ45-IP20 180°

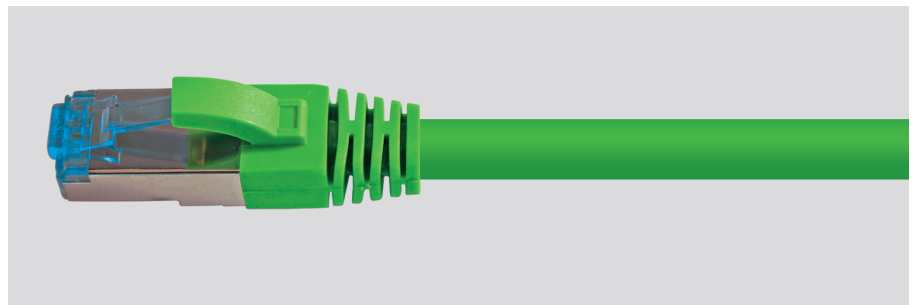

Category 6A



Type

Patch Cable RJ45-IP20 180°, Industrial Ethernet Cat.6A extra flexible applications

Cable

Designation:

S/FTP 4x2xAWG 26/7 LSZH

Sheath material:

LSZH

Frequency:

up to 500 MHz

Plug

Push-on connector type 1:

RJ45 8(8)

Push-on connector type 2:

RJ45 8(8)

System type:

HELUKAT® RJ45 Cat 6A

Pin assignment:

1:1 acc. to TIA/EIA 568 B

Norms and standards

Components of HELUKAT® CONNECTING SYSTEMS® to 500 MHz acc. Category 6A, ISO 11801 (2002), EN 50173-3, IEC61156-1, IEC61156-6, EIA/TIA 568 B and IEC 61918.

Preferred types

Part no.	Sheath colour	Length in metres	Unit
11007747	green similar RAL 6018	0,15	100
11007748	green similar RAL 6018	0,25	100
11007749	green similar RAL 6018	0,5	50
11007750	green similar RAL 6018	1,0	50
11007751	green similar RAL 6018	1,5	50
11007752	green similar RAL 6018	2,0	50
11007753	green similar RAL 6018	3,0	30
11007754	green similar RAL 6018	5,0	30
11007755	green similar RAL 6018	7,5	25
11007756	green similar RAL 6018	10,0	25
11007757	green similar RAL 6018	15,0	10

Dimensions and specifications may be changed without prior notice.

Characteristics

Jumper cable for the connection between IP20 protected ethernet applications according ISO/IEC 11801 with RJ45 plugs. Usable for normal extra flexible applications.