
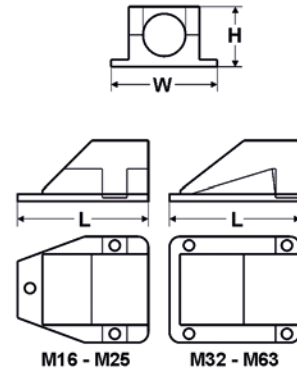


WVF

for simple cable insertion

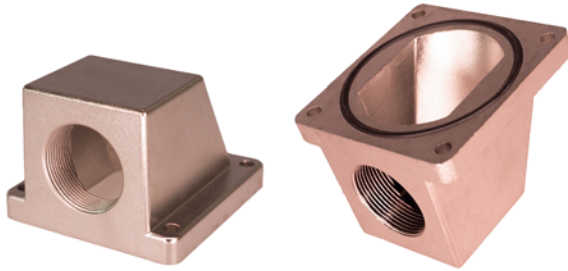

TECHNICAL DATA

Zinc elbow flange

Temperature range -40°C to +150°C
Protection class IP 68 - 10 bar

■ STRUCTURE

- Material: Zinc die casting nickel plated
- O-ring: Hydrogenated nitrile-butadiene rubber (HNBR)

■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

■ NOTES

- Legend:
Dimensions
H - Height
W - Width
L - Length

metric thread – female

Part no.	Size inside	Height mm	Width mm	Length mm	Packaging unit (in pc.)
11026143	M16 x 1.50	30	45.0	48.0	10
11026144	M20 x 1.50	35	53.0	56.0	10
11026145	M25 x 1.50	42	63.0	65.0	10
11026146	M32 x 1.50	52	70.0	75.0	5

Part no.	Size inside	Height mm	Width mm	Length mm	Packaging unit (in pc.)
11026147	M40 x 1.50	52	71.0	75.0	5
11026148	M50 x 1.50	69	89.0	93.0	2
11026149	M63 x 1.50	74	96.0	114.0	1