


Patch Cables PROFinet A

RJ45-HAN® 3A-IP67 180°

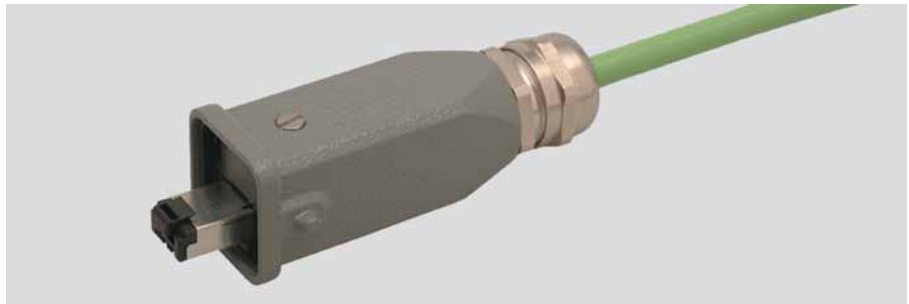

Category 5e



Type

Patch Cable RJ45 HARTING HAN® 3A IP67, PROFinet A fixed installation

Cable

Designation: PROFinet type A (SK)
Sheath material: PVC
Frequency: up to 100 MHz

Plug

Push-on connector type 1: RJ45-connector IP67
Push-on connector type 2: RJ45-connector IP67
System type: Harting IP67 HAN® 3A metal
Pin assignment: 1:1 acc. to TIA/EIA 568 B

Flame proof

acc. to IEC 60332-1-2

Oil-resistant

Acc. to EN60811-2-1

Norms and standards

Components of HELUKAT® CONNECTING SYSTEMS® to 100 MHz acc. Categorie 5, ISO 11801 (2002), EN 50173-3, IEC 61156-1, IEC 61156-5, EIA/TIA 568 B and IEC 61918. Support the PROFinet guideline V4.0 (2017).

Preferred types

Part no.	Sheath colour	Length in metres	Unit
801342	green	0,5	10
801343	green	1,0	10
801344	green	2,0	10
801345	green	3,0	10
801346	green	5,0	10
801347	green	10,0	10
801365	green	15,0	10
801366	green	50,0	5
801367	green	100,0	1

Dimensions and specifications may be changed without prior notice.

Characteristics

Jumper cable for the connection between IP67 protected ethernet applications according ISO/IEC 11801 with RJ45 plugs. Usable for fixed installation cabling.

Options

We also can deliver other cable length, cross-over cables or other types of plugs.