


## Type Preferred types

Plug type:

ST / ST

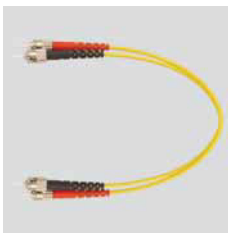


### Jumper cable I-VH 2x1 (glas fibre)

Part no.	Fibre type	Length in metres	Sheath colour	Unit
803161	Multimode G50/125 OM2	1	Orange	10
80983	Multimode G50/125 OM2	2	Orange	10
801175	Multimode G50/125 OM2	3	Orange	10
801176	Multimode G50/125 OM2	5	Orange	10
805796	Multimode G50/125 OM3	1	turquoise	10
802442	Multimode G50/125 OM3	2	turquoise	10
805797	Multimode G50/125 OM3	3	turquoise	10
805798	Multimode G50/125 OM3	5	turquoise	10
80636	Multimode G62.5/125	2	Orange	10
805799	Single-mode E9/125	1	Yellow	10
81043	Single-mode E9/125	2	Yellow	10
805800	Single-mode E9/125	3	Yellow	10
805801	Single-mode E9/125	5	Yellow	10

Plug type:


SC duplex / ST

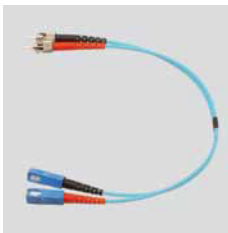

Part no.	Fibre type	Length in metres	Sheath colour	Unit
803163	Multimode G50/125 OM2	1	Orange	10
81053	Multimode G50/125 OM2	2	Orange	10
803164	Multimode G50/125 OM2	3	Orange	10
803165	Multimode G50/125 OM2	5	Orange	10
805790	Multimode G50/125 OM3	1	turquoise	10
802444	Multimode G50/125 OM3	2	turquoise	10
81055	Single-mode E9/125	2	Yellow	10
805791	Multimode G50/125 OM3	3	turquoise	10
805792	Multimode G50/125 OM3	5	turquoise	10
81054	Multimode G62.5/125	2	Orange	10
805793	Single-mode E9/125	1	Yellow	10
805794	Single-mode E9/125	3	Yellow	10
805795	Single-mode E9/125	5	Yellow	10

Plug type:

SC duplex / SC duplex

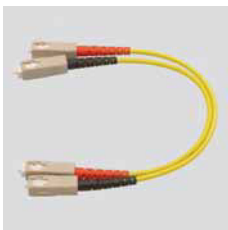


Part no.	Fibre type	Length in metres	Sheath colour	Unit
803162	Multimode G50/125 OM2	1	Orange	10
81050	Multimode G50/125 OM2	2	Orange	10
805078	Multimode G50/125 OM3	1	turquoise	10
802443	Multimode G50/125 OM3	2	turquoise	10
805079	Multimode G50/125 OM3	3	turquoise	10
805712	Multimode G50/125 OM3	5	turquoise	10
81051	Multimode G62.5/125	2	Orange	10
800423	Single-mode E9/125	1	Yellow	10
81052	Single-mode E9/125	2	Yellow	10
800424	Single-mode E9/125	3	Yellow	10
805715	Single-mode E9/125	5	Yellow	10

Continuation ►

Plug type:


LC duplex / LC duplex

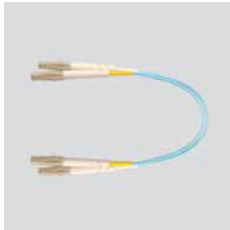

Part no.	Fibre type	Length in metres	Sheath colour	Unit
803166	Multimode G50/125 OM2	1	Orange	10
802447	Multimode G50/125 OM2	2	Orange	10
803167	Multimode G50/125 OM2	3	Orange	10
803168	Multimode G50/125 OM2	5	Orange	10
805076	Multimode G50/125 OM3	1	turquoise	10
802445	Multimode G50/125 OM3	2	turquoise	10
805077	Multimode G50/125 OM3	3	turquoise	10
805714	Multimode G50/125 OM3	5	turquoise	10
802449	Multimode G62.5/125	2	Orange	10
805045	Single-mode E9/125	1	Yellow	10
802451	Single-mode E9/125	2	Yellow	10
805046	Single-mode E9/125	3	Yellow	10
805717	Single-mode E9/125	5	Yellow	10

Plug type:


LC duplex / ST

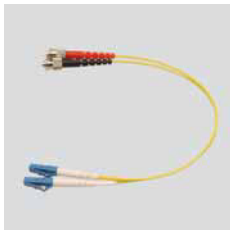

Part no.	Fibre type	Length in metres	Sheath colour	Unit
803171	Multimode G50/125 OM2	1	Orange	10
803172	Multimode G50/125 OM2	3	Orange	10
803173	Multimode G50/125 OM2	5	Orange	10
805802	Multimode G50/125 OM3	1	turquoise	10
803174	Multimode G50/125 OM3	2	turquoise	10
805804	Multimode G50/125 OM3	3	turquoise	10
805803	Multimode G50/125 OM3	5	turquoise	10
803175	Multimode G62.5/125	2	Orange	10
805805	Single-mode E9/125	1	Yellow	10
803176	Single-mode E9/125	2	Yellow	10
805807	Single-mode E9/125	3	Yellow	10
805806	Single-mode E9/125	5	Yellow	10

Plug type:

LC duplex / SC duplex

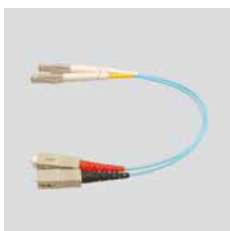

Part no.	Fibre type	Length in metres	Sheath colour	Unit
803169	Multimode G50/125 OM2	1	Orange	10
802448	Multimode G50/125 OM2	2	Orange	10
803170	Multimode G50/125 OM2	5	Orange	10
805074	Multimode G50/125 OM3	1	turquoise	10
802446	Multimode G50/125 OM3	2	turquoise	10
805075	Multimode G50/125 OM3	3	turquoise	10
805713	Multimode G50/125 OM3	5	turquoise	10
802450	Multimode G62.5/125	2	Orange	10
802482	Single-mode E9/125	1	Yellow	10
802452	Single-mode E9/125	2	Yellow	10
801836	Single-mode E9/125	3	Yellow	10
805716	Single-mode E9/125	5	Yellow	10

Dimensions and specifications may be changed without prior notice.

## Application

## Options

Cable connections by HELUCOM® are used for wiring terminals.

On request, different assembly variations, such as E2000, FC/PC, F-SMA or DIN, are also available. 8° or 9° diagonal cross sections are also manufactured with the corresponding plug types.