


**Type**  
**Standard length**  
**Preferred types**

**Fibre pigtails**  
**2,0m**

Plug type:

ST

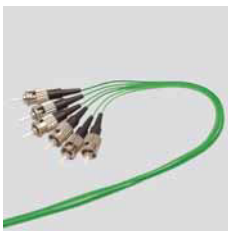

Part no.	Fibre type	Sheath colour	Unit
<b>80457</b>	Multimode G50/125 OM2	Green	12
<b>80606</b>	Multimode G62.5/125	Blue	12
<b>81041</b>	Single-mode E9/125	Yellow	12

Plug type:


SC



Part no.	Fibre type	Sheath colour	Unit
<b>81044</b>	Multimode G50/125 OM2	Green	12
<b>81045</b>	Multimode G62.5/125	Blue	12
<b>81046</b>	Single-mode E9/125	Yellow	12

Plug type:

ST

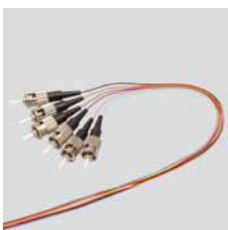

Part no.	Fibre type	Sheath colour	Unit
<b>805718</b>	Multimode G50/125 OM2	color coded	12
<b>805719</b>	Multimode G50/125 OM3	color coded	12
<b>805720</b>	Multimode G50/125 OM4	color coded	12
<b>805722</b>	Multimode G62.5/125	color coded	12
<b>805721</b>	Single-mode E9/125	color coded	12

Plug type:

SC



Part no.	Fibre type	Sheath colour	Unit
<b>805723</b>	Multimode G50/125 OM2	color coded	12
<b>805080</b>	Multimode G50/125 OM3	color coded	12
<b>805724</b>	Multimode G50/125 OM4	color coded	12
<b>805725</b>	Multimode G62.5/125	color coded	12
<b>805110</b>	Single-mode E9/125	color coded	12

Continuation ►

Plug type:

LC



Part no.	Fibre type	Sheath colour	Unit
<b>805726</b>	Multimode G50/125 OM2	color coded	12
<b>805727</b>	Multimode G50/125 OM3	color coded	12
<b>805728</b>	Multimode G50/125 OM4	color coded	12
<b>805730</b>	Multimode G62.5/125	color coded	12
<b>805729</b>	Single-mode E9/125	color coded	12

Dimensions and specifications may be changed without prior notice.

## Application

Pigtails are used in glass fibre sets, such as splice boxes. 12 pigtails with fibrecoatings 900µ in a packing unit. Every packing unit contains an individual measurement protocol.

## Options

On request, different assembly variations, such as E2000, FC/PC, F-SMA or DIN, are also available. 8° or 9° diagonal cross sections are also manufactured with the corresponding plug types.