


PA-OF

open

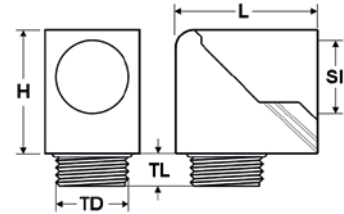

TECHNICAL DATA

PA folding profile

Temperature range -20°C to +80°C
Protection class IP 68

STRUCTURE

- Material: Polyamide (PA)
- O-ring: Nitrile butadiene rubber (NBR)

PROPERTIES

- halogen-free
- phosphor-free
- silicone-free
- cadmium-free

APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction
- For simple cable insertion. The profile can be re-opened at any time.

NOTES

- Legend:
Dimensions
TL - Thread Length
SI - Size of the internal thread

from metric to metric

Size	Thread length mm	Packaging unit (in pc.)	Spanner size mm	Height mm	Length mm	grey	black
						(RAL 7035) Part no.	(RAL 9005) Part no.
M16 x 1.5	8.0	25	19	23	28.5	90271	91835
M20 x 1.5	9.0	25	24	30.5	35.0	90272	91836
M25 x 1.5	11.0	10	33	40	49.0	90273	91837

from PG to PG

Size	Thread length mm	Packaging unit (in pc.)	Spanner size mm	Height mm	Length mm	grey	black
						(RAL 7035) Part no.	(RAL 9005) Part no.
PG 9	8.0	25	19	23	28.5	90383	97110
PG 11	8.0	25	22	27	31.5	90384	97502
PG 13.5	9.0	25	24	30.5	35.0	90385	97073
PG 16	10.0	25	27	32.5	37.5	90386	94781
PG 21	11.0	25	33	40	49.0	90387	94782