

UNI-DICHT-PA

Plastic sealing cable gland with colour-coded inserts made by TPE.

Material

Polyamide PA6-3
Seal: TPE

- halogen-free
- phosphor-free
- silicone-free
- cadmium-free

Properties

- Large-areas cable sealing
- Easy to assemble
- Large clamping areas


Note

Cable glands in black colour on request.
UL- and CSA- approval for use with TPE-V inserts, TPE-V inserts on request.

Technical data

Protection class: IP 68 - 10 bar

Temperature range: -20°C up to +100°C

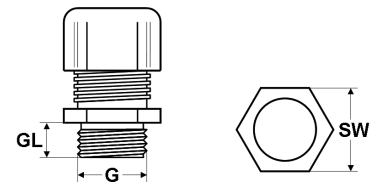

Dimensions

G Thread size
GL Thread length
SW Spanner size

metric thread

Part no.	Size Metr.	Sealing insert colour	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/100 items at a purchase of		
							up to 100	101 - 500	501 - 1000
903800	M12 x 1,5	yellow	4,0 - 6,5	8,0	15	50	o. r.	o. r.	o. r.
903801	M16 x 1,5	yellow	4,0 - 6,5	9,0	19	50	o. r.	o. r.	o. r.
903802	M16 x 1,5	grey	5,0 - 8,0	9,0	19	50	o. r.	o. r.	o. r.
903803	M16 x 1,5	black	6,5 - 9,5	9,0	19	50	o. r.	o. r.	o. r.
903804	M20 x 1,5	yellow	4,0 - 6,5	9,0	24	50	o. r.	o. r.	o. r.
903805	M20 x 1,5	grey	5,0 - 8,0	9,0	24	50	o. r.	o. r.	o. r.
903806	M20 x 1,5	black	6,5 - 9,5	9,0	24	50	o. r.	o. r.	o. r.
903807	M20 x 1,5	green	7,0 - 10,5	9,0	24	50	o. r.	o. r.	o. r.
903808	M20 x 1,5	red	9,0 - 13,0	9,0	24	50	o. r.	o. r.	o. r.
903809	M25 x 1,5	yellow	4,0 - 6,5	9,0	30	50	o. r.	o. r.	o. r.
903810	M25 x 1,5	grey	5,0 - 8,0	9,0	30	50	o. r.	o. r.	o. r.
903811	M25 x 1,5	black	6,5 - 9,5	9,0	30	50	o. r.	o. r.	o. r.
903812	M25 x 1,5	green	7,0 - 10,5	9,0	30	50	o. r.	o. r.	o. r.
903813	M25 x 1,5	red	9,0 - 13,0	9,0	30	50	o. r.	o. r.	o. r.
903814	M25 x 1,5	white	11,5 - 15,5	9,0	30	50	o. r.	o. r.	o. r.
903815	M32 x 1,5	green	7,0 - 10,5	11,0	36	25	o. r.	o. r.	o. r.
903816	M32 x 1,5	red	9,0 - 13,0	11,0	36	25	o. r.	o. r.	o. r.
903817	M32 x 1,5	white	11,5 - 15,5	11,0	36	25	o. r.	o. r.	o. r.
903818	M32 x 1,5	blue	14,0 - 18,0	11,0	36	25	o. r.	o. r.	o. r.
903819	M32 x 1,5	brown	17,0 - 20,5	11,0	36	25	o. r.	o. r.	o. r.
903820	M40 x 1,5	blue	14,0 - 18,0	11,5	46	10	o. r.	o. r.	o. r.
903821	M40 x 1,5	brown	17,0 - 20,5	11,5	46	10	o. r.	o. r.	o. r.
903822	M40 x 1,5	orange	20,0 - 25,0	11,5	46	10	o. r.	o. r.	o. r.
903823	M40 x 1,5	light yellow	24,0 - 28,0	11,5	46	10	o. r.	o. r.	o. r.
903824	M50 x 1,5	anthracite	27,0 - 32,0	14,0	56	5	o. r.	o. r.	o. r.
903825	M50 x 1,5	light blue	29,0 - 34,0	14,0	56	5	o. r.	o. r.	o. r.
904295	M50 x 1,5	pink	32,0 - 36,0	14,0	56	5	o. r.	o. r.	o. r.

Continuation ►

UNI-DICHT-PA cable gland



PG thread

Part no.	Size PG	Sealing insert colour	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/ 100 items at a purchase of		
							up to 100	101 - 500	501 - 1000
903826	9	yellow	4,0 - 6,5	9,0	19	50	o. r.	o. r.	o. r.
903827	9	grey	5,0 - 8,0	9,0	19	50	o. r.	o. r.	o. r.
903828	9	black	6,5 - 9,5	9,0	19	50	o. r.	o. r.	o. r.
903829	11	yellow	4,0 - 6,5	9,0	22	50	o. r.	o. r.	o. r.
903830	11	grey	5,0 - 8,0	9,0	22	50	o. r.	o. r.	o. r.
903831	11	black	6,5 - 9,5	9,0	22	50	o. r.	o. r.	o. r.
903832	11	green	7,0 - 10,5	9,0	22	50	o. r.	o. r.	o. r.
903833	13,5	yellow	4,0 - 6,5	9,0	24	50	o. r.	o. r.	o. r.
903834	13,5	grey	5,0 - 8,0	9,0	24	50	o. r.	o. r.	o. r.
903835	13,5	black	6,5 - 9,5	9,0	24	50	o. r.	o. r.	o. r.
903836	13,5	green	7,0 - 10,5	9,0	24	50	o. r.	o. r.	o. r.
903837	13,5	red	9,0 - 13,0	9,0	24	50	o. r.	o. r.	o. r.
903838	16	yellow	4,0 - 6,5	9,0	27	50	o. r.	o. r.	o. r.
903839	16	grey	5,0 - 8,0	9,0	27	50	o. r.	o. r.	o. r.
903840	16	black	6,5 - 9,5	9,0	27	50	o. r.	o. r.	o. r.
903841	16	green	7,0 - 10,5	9,0	27	50	o. r.	o. r.	o. r.
903842	16	red	9,0 - 13,0	9,0	27	50	o. r.	o. r.	o. r.
903843	16	white	11,5 - 15,5	9,0	27	50	o. r.	o. r.	o. r.
903844	21	green	7,0 - 10,5	11,0	33	25	o. r.	o. r.	o. r.
903845	21	red	9,0 - 13,0	11,0	33	25	o. r.	o. r.	o. r.
903846	21	white	11,5 - 15,5	11,0	33	25	o. r.	o. r.	o. r.
903847	21	blue	14,0 - 18,0	11,0	33	25	o. r.	o. r.	o. r.
903848	21	brown	17,0 - 20,5	11,0	33	25	o. r.	o. r.	o. r.
903849	29	blue	14,0 - 18,0	11,0	43	10	o. r.	o. r.	o. r.
903850	29	brown	17,0 - 20,5	11,0	43	10	o. r.	o. r.	o. r.
903851	29	orange	20,0 - 25,0	11,0	43	10	o. r.	o. r.	o. r.
903852	29	light yellow	24,0 - 28,0	11,0	43	10	o. r.	o. r.	o. r.
903853	36	anthracite	27,0 - 32,0	14,0	53	5	o. r.	o. r.	o. r.
903854	36	light blue	29,0 - 34,0	14,0	53	5	o. r.	o. r.	o. r.
903855	36	pink	32,0 - 36,0	14,0	53	5	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request