


UNI-DICHT-SI

colour coded

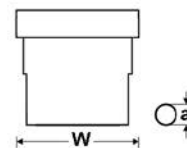

TECHNICAL DATA

TPE sealing insert

Temperature range -40°C to +130°C

STRUCTURE

- Material: thermoplastic elastomers (TPE)

PROPERTIES

- halogen-free
- phosphor-free
- silicone-free
- cadmium-free

APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction
- For use with UNI-DICHT gland bodies made by polyamide or by brass.

NOTES

- The UNI-DICHT sealing inserts M20x1,5 (part no. 903961 up to 903965) can be used only with UNI-DICHT-VK-PA M20x1,5 (part no. 90831).
- The UNI-DICHT sealing inserts M20x1,5 (part no. 903966 up to 903970) can be used only with UNI-DICHT-VK-MS M20x1,5 (part no. 904213).
- The UNI-DICHT sealing insert PG21 (part no. 903981) can be used only with UNI-DICHT-VK-MS PG21 (part no. 904226).
- The UNI-DICHT sealing insert M32x1,5 (part no. 903981) can be used only with UNI-DICHT-VK-MS M32x1,5 (part no. 904216).
- Legend:
 - Dimensions
 - W - Width
 - a - Diameter of stud hole

Part no.	Size	Size	Sealing insert colour	Cable Ø from / to mm	Packaging unit (in pc.)
903952		M12 x 1.5	yellow	4.0 - 6.5	100
903961		M20 x 1.5	yellow	4.0 - 6.5	100
903962		M20 x 1.5	grey	5.0 - 8.0	100
903964		M20 x 1.5	green	7.0 - 10.5	100
903965		M20 x 1.5	red	9.0 - 13.0	100
903963		M20 x 1.5	black	6.5 - 9.5	100
903953	PG 7		yellow	4.0 - 6.5	100
903954	PG 9	M16 x 1.5	yellow	4.0 - 6.5	100
903955	PG 9	M16 x 1.5	grey	5.0 - 8.0	100
903956	PG 9	M16 x 1.5	black	6.5 - 9.5	100
903957	PG 11	M20 x 1.5	yellow	4.0 - 6.5	100
903958	PG 11	M20 x 1.5	grey	5.0 - 8.0	100
903960	PG 11	M20 x 1.5	green	7.0 - 10.5	100
903959	PG 11	M20 x 1.5	black	6.5 - 9.5	100
903966	PG 13.5	M20 x 1.5	yellow	4.0 - 6.5	100
903967	PG 13.5	M20 x 1.5	grey	5.0 - 8.0	100

Part no.	Size	Size	Sealing insert colour	Cable Ø from / to mm	Packaging unit (in pc.)
903969	PG 13.5	M20 x 1.5	green	7.0 - 10.5	100
903970	PG 13.5	M20 x 1.5	red	9.0 - 13.0	100
903968	PG 13.5	M20 x 1.5	black	6.5 - 9.5	100
903971	PG 16	M25 x 1.5	yellow	4.0 - 6.5	100
903972	PG 16	M25 x 1.5	grey	5.0 - 8.0	100
903974	PG 16	M25 x 1.5	green	7.0 - 10.5	100
903975	PG 16	M25 x 1.5	red	9.0 - 13.0	100
903973	PG 16	M25 x 1.5	black	6.5 - 9.5	100
903976	PG 16	M25 x 1.5	white	11.5 - 15.5	100
903980	PG 21	M32 x 1.5	blue	14.0 - 18.0	50
903981	PG 21	M32 x 1.5	brown	17.0 - 20.5	50
903977	PG 21	M32 x 1.5	green	7.0 - 10.5	50
903978	PG 21	M32 x 1.5	red	9.0 - 13.0	50
903979	PG 21	M32 x 1.5	white	11.5 - 15.5	50
903986	PG 29	M40 x 1.5	light yellow	24.0 - 28.0	25
903983	PG 29	M40 x 1.5	blue	14.0 - 18.0	25

Continued on next page

UNI-DICHT-SI



colour coded

Part no.	Size	Size	Sealing insert colour	Cable Ø from / to mm	Packaging unit (in pc.)
903984	PG 29	M40 x 1.5	brown	17.0 - 20.5	25
903985	PG 29	M40 x 1.5	orange	20.0 - 25.0	25
903982	PG 29	M40 x 1.5	white	11.5 - 15.5	25

Part no.	Size	Size	Sealing insert colour	Cable Ø from / to mm	Packaging unit (in pc.)
903989	PG 36	M50 x 1.5	pink	32.0 - 36.0	10
903990	PG 42	M50 x 1.5	white	36.0 - 40.0	10
903991	PG 48	M63 x 1.5	white	39.0 - 44.0	10