


# PBE-K

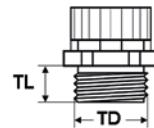

## TECHNICAL DATA

PA pressure balance element

Temperature range -20°C to +105°C  
Protection class IP 68 / IP 69K

## STRUCTURE

- Material: Polyamide (PA) 6
- with semi permeable membrane that allows air flow but blocks moisture

## APPLICATION

- Machine and plant construction
- Installation technology
- Control cabinet construction

## NOTES

- Legend:
  - Dimensions
  - TD - Thread Diameter
  - TL - Thread Length
  - SZ - Spanner Size

## metric thread

Size	Spanner size mm	Thread length mm	Packaging unit (in pc.)	Part no.	Part no.
M12 x 1.5	17	6.6	100	<b>904492</b>	<b>904494</b>
M12 x 1.5	17	10.0	100	<b>904493</b>	<b>904495</b>