


# VM-ZE

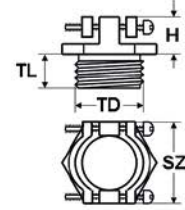

## TECHNICAL DATA

Nickel plated brass strain relief

Temperature range up to +200°C

### ■ STRUCTURE

- Material: Brass, nickel plated

### ■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

### ■ NOTES

- Legend:  
 Dimensions  
 TD - Thread Diameter  
 TL - Thread Length  
 SZ - Spanner Size  
 H - Height without thread

#### metric thread

Part no.	Size	Thread length mm	Spanner size mm	Height mm	Packaging unit (in pc.)
905877	M12 x 1.5	5.5	16	9.5	100
905878	M16 x 1.5	6.0	19	10	100
905879	M20 x 1.5	6.5	24	11.5	50
905880	M25 x 1.5	8.0	34	13	25

Part no.	Size	Thread length mm	Spanner size mm	Height mm	Packaging unit (in pc.)
905881	M32 x 1.5	8.0	42	14	25
905882	M40 x 1.5	9.5	52	16	25
905883	M50 x 1.5	9.5	52	16	10

#### PG thread

Part no.	Size	Thread length mm	Spanner size mm	Height mm	Packaging unit (in pc.)
99049	PG 7	5.5	16	9.3	100
99050	PG 9	6.0	19	10.6	100
99051	PG 11	6.0	22	10.7	100
99052	PG 13.5	6.5	24	11.3	50
99053	PG 16	6.5	26	11.8	50

Part no.	Size	Thread length mm	Spanner size mm	Height mm	Packaging unit (in pc.)
99054	PG 21	7.5	33	13.3	50
99055	PG 29	8.0	42	13.8	25
99056	PG 36	9.5	52	15.8	10
99057	PG 42	10.0	59	16.3	10
99058	PG 48	11.0	64	16.3	5