


HELUTOP® SP

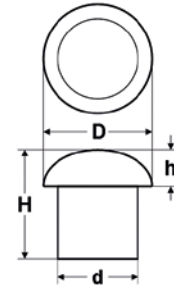

TECHNICAL DATA

PA-Sealing plug

■ STRUCTURE

- Material: Polyamide (PA) 6

■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction
- For sealing of not assigned cable glands HELUTOP® HT.

■ NOTES

- Colours: black
- Protection tab 903492 only for cable glands type HELUTOP® with clamping range 5-10mm.
- Legend:
 - Dimensions
 - H - Height
 - H - Height without thread
 - D - Outer diameter
 - D - Outer diameter of upper part

Part no.	Size	Size	Clamping area from / up to mm	Outer Ø of upper part mm	Outer dimensions mm, approx.	Height mm	Hight without thread mm	Packaging unit (in pc.)
905924	M12 x 1.5	PG 7	3.00 - 6.50	9.2	6.4	11	4	100
905925	M16 x 1.5	PG 9	4.00 - 8.00	10.5	8.0	16	5	100
903492	M16 x 1.5	PG 11	5.00 - 10.00	13.3	9.7	20.7	5.7	100
903493	M20 x 1.5	PG 13.5	6.00 - 12.00	15.8	12.0	18	8	100
905928	M20 x 1.5	PG 16	10.00 - 14.00	19	13.6	18.7	8.7	100
903494	M25 x 1.5		11.00 - 17.00	19.9	16.4	18.3	7.3	50
905929	M25 x 1.5	PG 21	13.00 - 18.00	22.2	17.8	21	9.7	100
903495	M32 x 1.5		15.00 - 21.00	24.1	20.4	21.2	9.2	100
903496	M40 x 1.5		19.00 - 28.00	32	27.5	25	9	100