
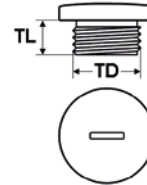


VS-O-SS

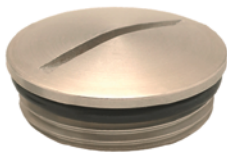

TECHNICAL DATA

Stainless steel screwed plug

Temperature range	-15°C to +200°C
Protection class	IP 68

■ STRUCTURE

- Material: Stainless steel 1.4305 / AISI 303
- O-ring: Fluoro rubber (FPM)
- with an O-ring made by FPM

■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

■ NOTES

- Legend:
Dimensions
TD - Thread Diameter
TL - Thread Length

metric thread

Part no.	Size	Thread length mm	Outer Ø mm, approx.	Height mm	Packaging unit (in pc.)
905946	M12 x 1.5	5.0	14.0	7.5	10
905947	M16 x 1.5	5.0	18.0	8	10
905948	M20 x 1.5	6.5	22.0	9.5	10
905949	M25 x 1.5	7.0	28.0	11	10

Part no.	Size	Thread length mm	Outer Ø mm, approx.	Height mm	Packaging unit (in pc.)
905950	M32 x 1.5	8.0	35.0	12	10
905951	M40 x 1.5	8.5	44.0	13	5
905952	M50 x 1.5	9.0	54.0	15	2
905953	M63 x 1.5	10.0	67.0	16	2