


# KM-INOX

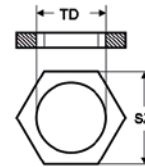

## TECHNICAL DATA

Stainless steel counter nut

Temperature range up to +200°C

### ■ STRUCTURE

- Material: Stainless steel 1.4305 / AISI 303

### ■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

### ■ NOTES

- Legend:  
Dimensions  
TD - Thread Diameter  
SZ - Spanner Size

#### metric thread – female

Part no.	Size	Spanner size mm	Packaging unit (in pc.)
920605	M12 x 1.5	15	10
920606	M16 x 1.5	19	10
920607	M20 x 1.5	24	10
920608	M25 x 1.5	30	10

Part no.	Size	Spanner size mm	Packaging unit (in pc.)
920609	M32 x 1.5	36	5
920610	M40 x 1.5	46	5
920611	M50 x 1.5	60	2
920612	M63 x 1.5	70	1

#### PG thread – female

Part no.	Size	Spanner size mm	Packaging unit (in pc.)
92970	PG 7	17	100
92971	PG 9	19	100
92972	PG 11	22	100
92973	PG 13.5	24	100

Part no.	Size	Spanner size mm	Packaging unit (in pc.)
92974	PG 16	27	100
92975	PG 21	32	100
92976	PG 29	41	100
92977	PG 36	60	25