


VS-O

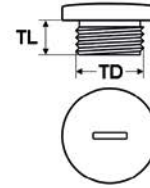

TECHNICAL DATA

Nickel plated brass screwed plug

Temperature range	-40°C to +80°C
Protection class	IP 68

■ STRUCTURE

- Material: Brass, nickel plated
- O-ring: Nitrile butadiene rubber (NBR)
- with an O-ring

■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

■ NOTES

- Legend:
Dimensions
TD - Thread Diameter
TL - Thread Length

metric thread

Size	Thread length mm	Packaging unit (in pc.)	Part no.
M12 x 1.5	5.0	100	92600
M16 x 1.5	5.0	100	92601
M20 x 1.5	6.0	100	92602
M25 x 1.5	7.0	100	92603

Size	Thread length mm	Packaging unit (in pc.)	Part no.
M32 x 1.5	8.0	50	92604
M40 x 1.5	8.0	50	92605
M50 x 1.5	9.0	25	92606
M63 x 1.5	10.0	10	92607

PG thread

Size	Thread length mm	Packaging unit (in pc.)	Part no.
PG 7	5.0	100	96763
PG 9	5.0	100	96169
PG 11	5.0	100	96889
PG 13.5	6.0	100	96654

Size	Thread length mm	Packaging unit (in pc.)	Part no.
PG 16	6.0	100	96170
PG 21	6.0	100	96171
PG 29	8.0	50	96650
PG 36	9.0	25	96649