


VSK-PA

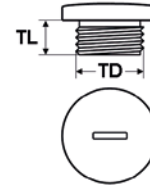

TECHNICAL DATA

PA screwed plug

Temperature range -40°C to +100°C
Protection class IP 54

STRUCTURE

- Material: Polyamide (PA)

PROPERTIES

- halogen-free
- phosphor-free

APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

NOTES

- Legend:
Dimensions
TD - Thread Diameter
TL - Thread Length

metric thread

Size	Thread length mm	Packaging unit (in pc.)	grey	grey	black
			(RAL 7035) Part no.	(RAL 7001) Part no.	(RAL 9005) Part no.
M12 x 1.5	6.0	100	94700	94980	94750
M16 x 1.5	7.0	100	94701	94981	94751
M20 x 1.5	7.0	100	94702	94982	94752
M25 x 1.5	10.0	100	94703	94983	94753
M32 x 1.5	11.0	50	94704	94984	94754
M40 x 1.5	13.0	50	94705	94985	94755
M50 x 1.5	14.0	25	94706	94986	94756
M63 x 1.5	15.0	25	94707	94987	94757

PG thread

Size	Thread length mm	Packaging unit (in pc.)	grey	grey	black
			(RAL 7035) Part no.	(RAL 7001) Part no.	(RAL 9005) Part no.
PG 7	6.0	100	96593	94970	96997
PG 9	6.5	100	96179	94971	96998
PG 11	6.5	100	96180	94972	96999
PG 13.5	6.5	100	96181	94973	97000

Continued on next page

VSK-PA

Size	Thread length mm	Packaging unit (in pc.)	grey (RAL 7035)	grey (RAL 7001)	black (RAL 9005)
			Part no.	Part no.	Part no.
PG 16	6.5	100	96182	94974	97001
PG 21	8.0	50	96183	94975	97002
PG 29	8.0	25	96184	94976	96527
PG 36	10.0	25	96185	-	97004
PG 42	10.0	25	96960	94978	97005
PG 48	12.0	25	96961	94979	97006