


# KVA MFDE

with Soft PVC

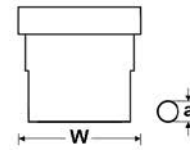

## TECHNICAL DATA

PVC multiple sealing insert

Temperature range -20°C to +105°C

### ■ STRUCTURE

- Material: Soft PVC

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction
- For use with KVA gland bodies.

### ■ APPLICATION

### ■ NOTES

- Legend:  
Dimensions  
W - Width  
a - Diameter of stud hole

Part no.	Size	Size	Sealing insert colour	Number holes x cable-Ø mm	Packaging unit (in pc.)
96050	PG 9	M16 x 1.5	white	2 x 1.0	100
96051	PG 9	M16 x 1.5	white	2 x 3.0	100
96052	PG 9	M16 x 1.5	white	4 x 3.0	100
96053	PG 9	M16 x 1.5	white	2 x 4.0	100
96054	PG 9	M16 x 1.5	white	1 x 5.0	100
96055	PG 11	M20 x 1.5	white	6 x 2.0	100
96058	PG 11	M20 x 1.5	white	2 x 3.0	100
96059	PG 11	M20 x 1.5	white	3 x 3.0	100
96485	PG 11	M20 x 1.5	white	2 x 4.0	100
97277	PG 11	M20 x 1.5	white	4 x 4.0	100
96060	PG 11	M20 x 1.5	white	2 x 5.0	100
96062	PG 13.5	M20 x 1.5	white	3 x 2.0	100
96063	PG 13.5	M20 x 1.5	white	10 x 2.0	100
96064	PG 13.5	M20 x 1.5	white	2 x 3.0	100
96065	PG 13.5	M20 x 1.5	white	3 x 3.0	100
96621	PG 13.5	M20 x 1.5	white	3 x 4.0	100
96067	PG 13.5	M20 x 1.5	white	2 x 5.0	100
96068	PG 13.5	M20 x 1.5	white	2 x 6.0	100
96069	PG 16	M25 x 1.5	white	7 x 2.0	50
96438	PG 16	M25 x 1.5	white	3 x 3.0	50
97512	PG 16	M25 x 1.5	white	5 x 3.0	50
97513	PG 16	M25 x 1.5	white	7 x 3.0	50
96436	PG 16	M25 x 1.5	white	8 x 3.0	50
96070	PG 16	M25 x 1.5	white	2 x 4.0	50
97472	PG 16	M25 x 1.5	white	3 x 4.0	50
96071	PG 16	M25 x 1.5	white	4 x 4.0	50

Part no.	Size	Size	Sealing insert colour	Number holes x cable-Ø mm	Packaging unit (in pc.)
97473	PG 16	M25 x 1.5	white	5 x 4.0	50
96072	PG 16	M25 x 1.5	white	6 x 4.0	50
96073	PG 16	M25 x 1.5	white	2 x 6.0	50
96723	PG 16	M25 x 1.5	white	3 x 6.0	100
96443	PG 16	M25 x 1.5	white	4 x 6.0	50
96074	PG 16	M25 x 1.5	white	3 x 7.0	50
96075	PG 16	M25 x 1.5	white	2 x 8.0	50
96076	PG 21	M32 x 1.5	white	21 x 2.0	50
96077	PG 21	M32 x 1.5	white	8 x 3.0	50
96078	PG 21	M32 x 1.5	white	6 x 4.0	50
96079	PG 21	M32 x 1.5	white	8 x 4.0	50
96080	PG 21	M32 x 1.5	white	4 x 5.0	50
96926	PG 21	M32 x 1.5	white	8 x 5.0	50
96714	PG 21	M32 x 1.5	white	6 x 5.5	25
96439	PG 21	M32 x 1.5	white	2 x 6.0	50
96081	PG 21	M32 x 1.5	white	4 x 6.0	50
96230	PG 21	M32 x 1.5	white	4 x 6.5	50
96231	PG 21	M32 x 1.5	white	5 x 6.5	50
96082	PG 21	M32 x 1.5	white	6 x 6.5	50
96083	PG 21	M32 x 1.5	white	3 x 7.0	50
96441	PG 21	M32 x 1.5	white	4 x 7.0	50
96445	PG 21	M32 x 1.5	white	2 x 8.0	50
96638	PG 21	M32 x 1.5	white	3 x 8.0	25
96084	PG 21	M32 x 1.5	white	4 x 8.0	50
96085	PG 21	M32 x 1.5	white	2 x 9.0	50
96232	PG 21	M32 x 1.5	white	3 x 9.0	50

Continued on next page

# KVA MFDE

## with Soft PVC

Part no.	Size	Size	Sealing insert colour	Number holes x cable-Ø mm	Packaging unit (in pc.)
96088	PG 29	M40 x 1.5	white	6 x 6.0	25
96086	PG 29	M40 x 1.5	white	10 x 6.0	25
96087	PG 29	M40 x 1.5	white	4 x 6.5	25
97289	PG 29	M40 x 1.5	white	8 x 6.5	25
96238	PG 29	M40 x 1.5	white	7 x 7.0	25
96089	PG 29	M40 x 1.5	white	6 x 8.0	25
96090	PG 29	M40 x 1.5	white	4 x 9.0	25
96091	PG 29	M40 x 1.5	white	5 x 9.0	25
96092	PG 29	M40 x 1.5	white	5 x 10.0	25
96093	PG 29	M40 x 1.5	white	2 x 11.0	25

Part no.	Size	Size	Sealing insert colour	Number holes x cable-Ø mm	Packaging unit (in pc.)
97448	PG 29	M40 x 1.5	white	3 x 11.0	25
96237	PG 29	M40 x 1.5	white	2 x 13.0	25
96095	PG 36	M50 x 1.5	white	15 x 5.0	25
97853	PG 36	M50 x 1.5	white	13 x 7.0	25
96235	PG 36	M50 x 1.5	white	7 x 9.0	25
96094	PG 36	M50 x 1.5	white	8 x 9.0	25
96096	PG 36	M50 x 1.5	white	3 x 10.0	25
96236	PG 36	M50 x 1.5	white	4 x 13.0	25
96097	PG 36	M50 x 1.5	white	2 x 15.0	25