


# ESD-DUO

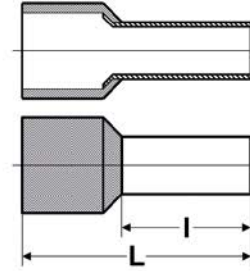

## TECHNICAL DATA

### Assortment box

#### ■ STRUCTURE

- Material: copper
- Surface: tinned
- Insulation: Polypropylene (PP)
- Assortment box: Polyvinyl chloride (PVC)

#### ■ APPLICATION

- Practical pocket sized assortment box. Refillable, split into 4 or 5 compartments, with cross-section lettering. Refilling with DUO core end sleeves.

#### ■ NOTES

- Empty cans:
  - ESD 7: 4-part with lettering 2x0.75 mm<sup>2</sup> / 2x1.0 mm<sup>2</sup> / 2x1.5 mm<sup>2</sup> / 2x2.5 mm<sup>2</sup>
  - ESD 8: 4-part with lettering 2x4.0 mm<sup>2</sup> / 2x6.0 mm<sup>2</sup> / 2x1.0 mm<sup>2</sup> / 2x16.0 mm<sup>2</sup>
- All sizes in regular length.
- Legend:
  - Dimensions
  - L - Length
  - l - Length to centre of hole

#### 50 x 0.75 / 50 x 1 / 50 x 1.5 / 50 x 2.5

Part no.	Type	Colour code	Packaging unit (in pc.)
96617	ESD 5	DIN	1

#### 20 x 4 / 10 x 6 / 10 x 10 / 5 x 16

Part no.	Type	Colour code	Packaging unit (in pc.)
96648	ESD 6	DIN	1

#### Empty cans

Part no.	Type	Colour code	Packaging unit (in pc.)
96629	ESD 7		1

Part no.	Type	Colour code	Packaging unit (in pc.)
96652	ESD 8		1