


VM-VS

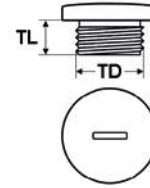

TECHNICAL DATA

Nickel plated brass screwed plug

Temperature range up to +200°C
Protection class IP 54

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

■ STRUCTURE

- Material: Brass, nickel plated

■ APPLICATION

■ NOTES

- Screw plugs for metric threads larger than M63x1,5 on request.
- Legend:
Dimensions
TD - Thread Diameter
TL - Thread Length

metric thread

Part no.	Size	Thread length mm	Packaging unit (in pc.)
98128	M12 x 1.5	5.0	100
98129	M16 x 1.5	5.0	100
98130	M20 x 1.5	6.5	100
98131	M25 x 1.5	7.0	100

Part no.	Size	Thread length mm	Packaging unit (in pc.)
98132	M32 x 1.5	8.0	50
98133	M40 x 1.5	8.5	50
98134	M50 x 1.5	9.0	25
98135	M63 x 1.5	10.0	10

PG thread

Part no.	Size	Thread length mm	Packaging unit (in pc.)
90620	PG 7	5.0	100
90621	PG 9	6.0	100
90622	PG 11	6.0	100
90623	PG 13.5	6.5	100
90624	PG 16	6.5	100

Part no.	Size	Thread length mm	Packaging unit (in pc.)
90625	PG 21	7.0	50
90626	PG 29	8.0	25
90627	PG 36	9.0	50
90628	PG 42	10.0	25
90629	PG 48	10.0	25