


# ZI-WV

for simple cable insertion

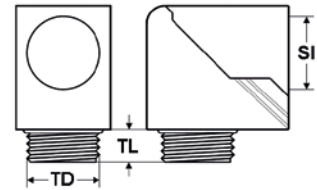

## TECHNICAL DATA

Zinc elbow

Temperature range -20°C to +100°C  
Protection class IP 65

## ■ STRUCTURE

- Material: Zinc die casting
- O-ring: Chloroprene rubber (CR)

## ■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction

## ■ NOTES

- Legend:  
Dimensions  
TD - Thread Diameter  
TL - Thread Length  
SI - Size of the internal thread

### from metric to metric

Part no.	Size outside	Thread length mm	Size inside	Height mm	Packaging unit (in pc.)
98561	M16 x 1.5	7.0	M16 x 1.5	25	25
98562	M20 x 1.5	7.0	M20 x 1.5	30	25

Part no.	Size outside	Thread length mm	Size inside	Height mm	Packaging unit (in pc.)
98563	M25 x 1.5	7.0	M25 x 1.5	35	25
98564	M32 x 1.5	10.0	M32 x 1.5	45	10