


O-Ring FPM

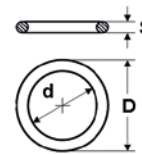

TECHNICAL DATA

FPM O-ring

Temperature range -40°C to +200°C

■ STRUCTURE

- Material: Fluoro rubber (FPM)

■ PROPERTIES

- halogen-free
- phosphor-free
- silicone-free
- cadmium-free

■ APPLICATION

- Machine and plant construction
- Robotics
- Automation technology
- Vehicle construction and shipbuilding
- Railway technology
- Installation technology
- Control cabinet construction
- For sealing against water, dust, and oil. Made by FPM for large temperature range.

■ NOTES

- Legend:
Dimensions
D - Outer diameter
d - Inner diameter
S - Strength

metric thread

Part no.	Size	Inner Ø mm	Outer Ø mm, approx.	Thickness mm	Packaging unit (in pc.)
98594	M12 x 1.5	10	13.0	1.5	100
98595	M16 x 1.5	12	15.0	1.5	100
98596	M20 x 1.5	17	20.6	1.8	100
904282	M25 x 1.5	22	26.0	2	100

Part no.	Size	Inner Ø mm	Outer Ø mm, approx.	Thickness mm	Packaging unit (in pc.)
904283	M32 x 1.5	29	33.0	2	100
904284	M40 x 1.5	35	39.0	2	100
904285	M50 x 1.5	43	47.0	2	100
904286	M63 x 1.5	55	59.0	2	50